


# Tube M62 hard anodized

Article number: 11185374

## Overview

- hard anodized lens protection with M62 thread
- optional tube extension with Tube Module 6mm (11185376), Tube Module 12 mm (11185375) or Tube Module 36 mm (11198906). Use of several Tube Modules possible.
- thread: M62
- length 58 mm

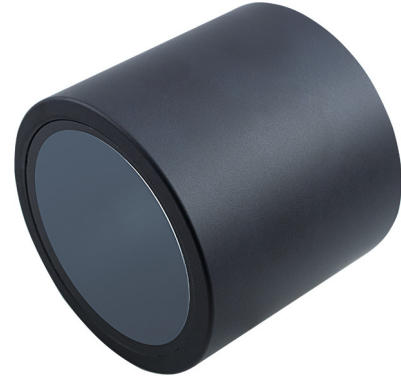

*Picture similar*

## Technical data


### Mechanical data

Inner diameter	61 mm
External diameter	65 mm
Material of cover glass	PMMA (acrylic glass)
Weight	≤ 76 g

### Mechanical data


Thread	M62 × 0,75
Ø cover glass	50 mm
Length of tube	58 mm
Material	aluminum, hard-anodized
Sealing	Gomastit 400

## Dimension drawing

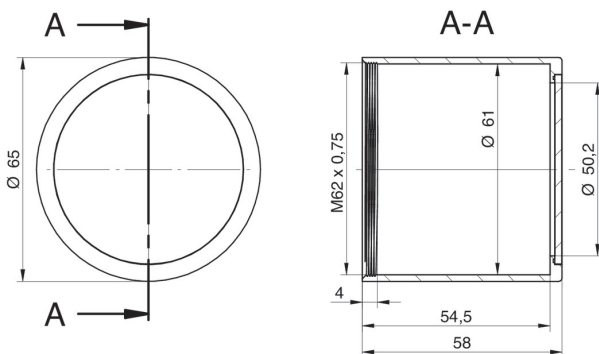


**Principle**

Optional accessories for protection class IP65/67:

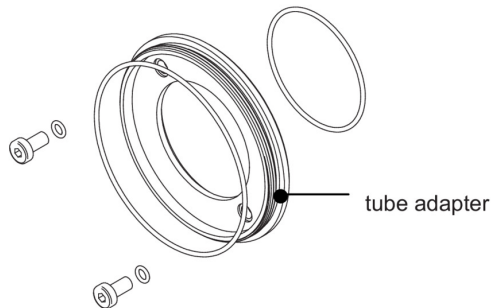

tube adapter

- hard-anodized, incl. sealing and screws  
 $\varnothing$  49,5 mm (VCXG.I 11185373)  
 $\varnothing$  65 mm (VCXG.I 11185377)  
 $\varnothing$  95 mm (VCXG.I 11704311)  
 $\varnothing$  65 mm (VLXT 11193125)  
 $\varnothing$  95 mm (VLXT.EF 11704315)

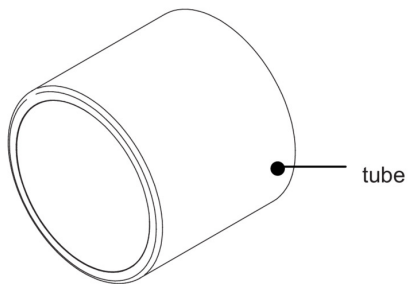

tube

- hard-anodized, cover glass PMMA  
 $\varnothing$  49,5 mm, Length 44 mm (11185370)  
 $\varnothing$  65 mm, Length 58 mm (11185374)  
 $\varnothing$  95 mm, length 70 mm (11704312)
- hard-anodized, tempered laminated safety glass  
 $\varnothing$  49,5 mm, Length 44 mm (11701124)  
 $\varnothing$  65 mm, Length 58 mm (11701125)