

# FKE 200CA600

Plastic fiber optic cable

Article number: 11708565

## Overview

- Diffuse type (array)
- Sensing distance up to 296 mm
- Rectangular sensing head, array width 60 mm, with integrated lens for fine line
- Plastic fiber 200 cm long, with bend protection
- Operating temperature up to +70 °C
- For compact fiber optic sensors FVDK 10 and OF10



Picture similar

## Technical data

### General data

Particular characteristics	Array (fine light barrier) Integrated lens Bend protection
----------------------------	--

Operating principle	Diffuse type
---------------------	--------------

Sensing distance Tw	296 mm
---------------------	--------

Fiber optic head	Rectangular
------------------	-------------

Operating temperature	-55 ... +70 °C
-----------------------	----------------

Exit angle	3°
------------	----

Fiber optics can be shortened to length	No
---	----

Integrated lens	Yes
-----------------	-----

Adaptable lens	No
----------------	----

Infrared light compatibility (1450 nm)	No
--	----

### General data

Smallest object recognizable	0.1 mm
------------------------------	--------

### Mechanical data

Array width	60 mm
-------------	-------

Width / diameter (head)	20 mm
-------------------------	-------

Height / length (head)	80 mm
------------------------	-------

Material (head)	Die-cast zinc
-----------------	---------------

Bending radius (fixed)	60 mm
------------------------	-------


Cable jacket diameter	2.8 mm
-----------------------	--------

Material cable jacket	PE
-----------------------	----


Material (fiber optic cable)	Plastic
------------------------------	---------

Length (fiber optic cable)	200 cm
----------------------------	--------

## Dimension drawing

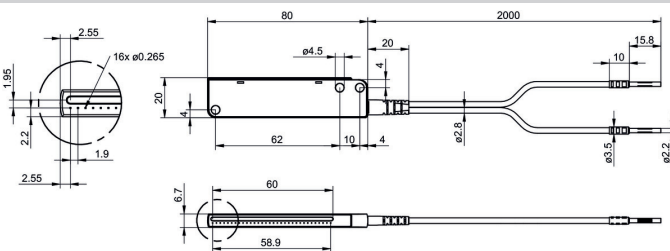

## Sensing distance diagram

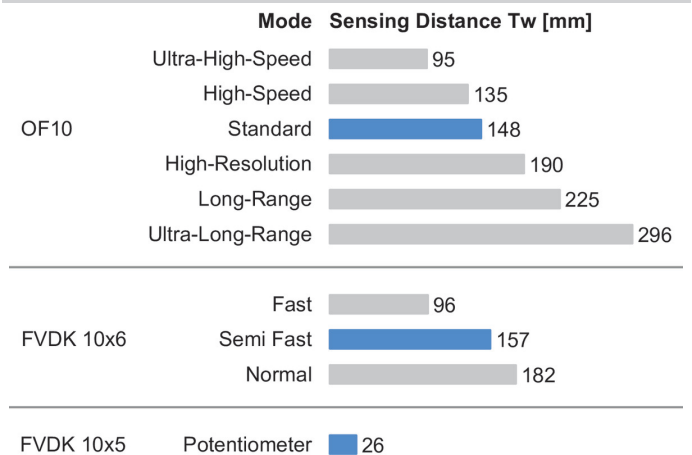

## FKE 200CA600

Plastic fiber optic cable

Article number: 11708565

### Accessories

#### Fitting fiber optic sensors

11252204	OF10.FR-GW2J.B2NV/A014
11244386	OF10.FR-GW2J.B2CV/A014
11224111	OF10.FR-PW1B.B2N
11224008	OF10.FR-NW1B.B2CV
11224009	OF10.FR-NW1B.B2N
11224110	OF10.FR-PW1B.B2CV
11244384	OF10.FR-GW2J.B2N/A014
10162867	FVDK 10N5101
10162865	FVDK 10N5101/S35A
10162866	FVDK 10P5101
10162864	FVDK 10P5101/S35A
11045446	FVDK 10N66Y0
11045448	FVDK 10N66Y0/S35A
11045460	FVDK 10N66YR
11045445	FVDK 10P66Y0
11045447	FVDK 10P66Y0/S35A
11045449	FVDK 10P66YR
11214490	FVDK 10P66ZR
11214493	FVDK 10P66Z0/S35A
11214478	FVDK 10P66Z0
11214492	FVDK 10N66ZR
11214494	FVDK 10N66Z0/S35A
11214479	FVDK 10N66Z0
11045462	FVDK 10N66YM
11045464	FVDK 10N66YS
11045461	FVDK 10P66YM
11045463	FVDK 10P66YS