

FUC 200C2Y00

Plastic fiber optic cable

Article number: 10135312

Overview

- Diffuse type
- Sensing distance up to 288 mm
- Cylindrical smooth sensing head $\varnothing 6$ mm, chemically resistant
- Plastic fiber 200 cm long
- Operating temperature up to +70 °C
- For compact fiber optic sensors FVDK 10 and OF10



Picture similar

Technical data

General data

Particular characteristics	Chemically resistant Smooth sensing head
----------------------------	---

Operating principle	Diffuse type
---------------------	--------------

Sensing distance Tw	170 mm
---------------------	--------

Fiber optic head	Cylindrical smooth
------------------	--------------------

Operating temperature	-30 ... +70 °C
-----------------------	----------------

Exit angle	60°
------------	-----

Fiber optics can be shortened to length	Yes
---	-----

Integrated lens	No
-----------------	----

Adaptable lens	No
----------------	----

Infrared light compatibility (1450 nm)	No
--	----

General data

Smallest object recognizable	0.1 mm
------------------------------	--------

Mechanical data

Diameter Fiber	1 mm
----------------	------

Width / diameter (head)	6 mm
-------------------------	------

Height / length (head)	16 mm
------------------------	-------

Material (head)	Stainless steel/PFA
-----------------	---------------------

Bending radius (fixed)	80 mm
------------------------	-------


Cable jacket diameter	2.2 mm
-----------------------	--------

Material cable jacket	PFA (chemically resistant)
-----------------------	----------------------------


Material (fiber optic cable)	Plastic
------------------------------	---------

Length (fiber optic cable)	200 cm
----------------------------	--------

Dimension drawing

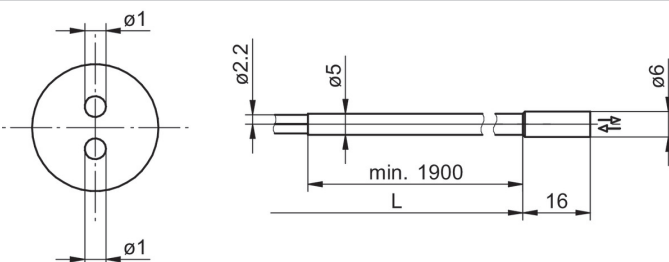

Fiber arrangement

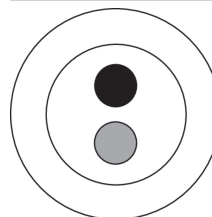


FUC 200C2Y00

Plastic fiber optic cable

Article number: 10135312

Sensing distance diagram

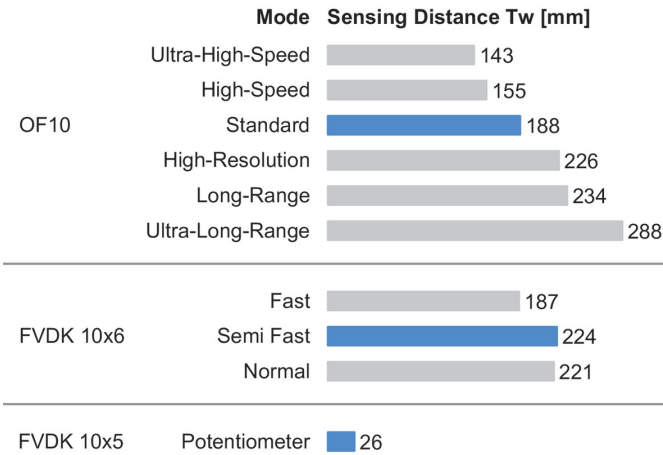

Accessories

Fitting fiber optic sensors

11252204	OF10.FR-GW2J.B2NV/A014
11244386	OF10.FR-GW2J.B2CV/A014
11224111	OF10.FR-PW1B.B2N
11224008	OF10.FR-NW1B.B2CV
11224009	OF10.FR-NW1B.B2N
11224110	OF10.FR-PW1B.B2CV
11244384	OF10.FR-GW2J.B2N/A014
10162867	FVDK 10N5101
10162865	FVDK 10N5101/S35A
10162866	FVDK 10P5101
10162864	FVDK 10P5101/S35A
11045446	FVDK 10N66Y0
11045448	FVDK 10N66Y0/S35A
11045460	FVDK 10N66YR
11045445	FVDK 10P66Y0
11045447	FVDK 10P66Y0/S35A
11045449	FVDK 10P66YR
11214490	FVDK 10P66ZR
11214493	FVDK 10P66Z0/S35A
11214478	FVDK 10P66Z0
11214492	FVDK 10N66ZR
11214494	FVDK 10N66Z0/S35A
11214479	FVDK 10N66Z0
11045462	FVDK 10N66YM
11045464	FVDK 10N66YS
11045461	FVDK 10P66YM
11045463	FVDK 10P66YS

Mounting accessories

10114652	Cutting tool for plastic fiber optics
10119911	Mounting bracket Ø 2,2 mm
10156738	Fiber optic cable extension 2 m
10158142	Fiber optic cable extension 5 m
10145523	Fiber optic cable extension 5 m highly flexible